



Datacom Connectivity



Cat6 UTP Keystone Jack 180°

Issue date: 10-10-14

Supersedes: 02/10



Value Innovation is a way of looking at the world. By combining market insight with technological know-how and building strong, long-lasting relationships, we add value to your business with advanced communication solutions and services that are designed to last. No matter how complex your challenge, we have a product or solution that will do more than meet your needs. New applications, breakthrough cables or complete network designs - it's all part of what we call Value Innovation, and it's what drives us.



Cat6 UTP Keystone Jack 180°





- Cat6 compliant performance
- Fully compatible with our full range of faceplates
- Fits into 25 mm back-box
- Fits into standard floor box plates

Specification

Item	Description
RJ45 Plastic housing	ABS + PC
RJ45 jack contact material and finish	Phosphor Bronze
	Contact area : Min 3 mm 50 micro-inch Gold plated over Nickel colour
IDC terminal and finish	Phosphor Bronze with min, 50 micro-inch Tin plated
Wire size compatibility	23-26 AWG solid wire
Housing	ABS
Dimensions	31mm x 21mm x 16.5mm

Performance

IDC cap colour code supports both wiring schemes TIA 568A & 568B	
Insertion force	900 gm for 8 contacts
Retention strength	7.7kg between jack and plug
Operating temperature	-10°C to 60°C
Durability	Jack 750 cycles

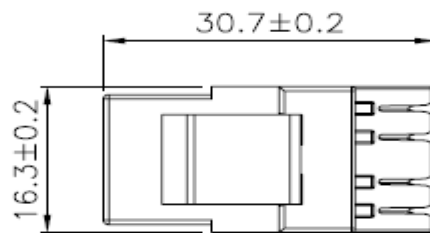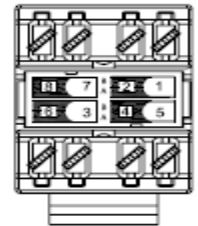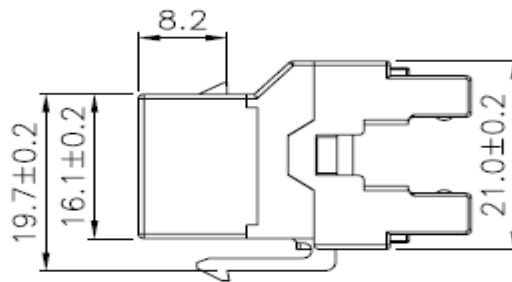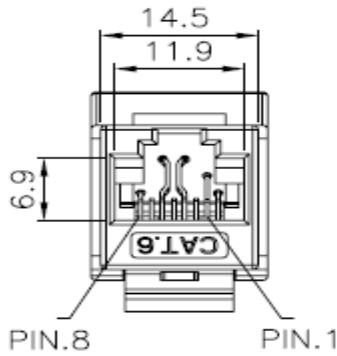

Technical data

Material code	SAP Descriptions	Material Description	Weight	Items per packaging unit
1021268	UC C400 MJ TR U BK	Cat6 UTP Keystone Jack 180°	8 g	1 or 50
Related Products				
Material code	Material Description		Weight	Items per packaging unit
1021333	UC CACC AA 01 EU		8 g	1 or 50
1021337	UC CACC MA 01 6C		8 g	1 or 50
1021338	UC CACC AA 01 6C		8 g	1 or 50
1021329	UC CACC MA 01 EU		8 g	1 or 50