

UC^{CONNECT} 1U 24port Cat6 UTP 180° Punch Down Panel



Cat6 Unshielded 24-Port Punch Down Patch Panel

- Cat6 compliant performance
- 180° termination blocks for easy termination
- Compatible with 110 & Krone Punch Tools
- Lasermark labels available on request


Specification



Item	Description
Panel	SPCC, 1.2 mm thickness
RJ45 jack contact material and finish	Phosphor Bronze Contact area : Min 3 mm 50 micro-inch Gold plated over Nickel colour
IDC terminal and finish	Phosphor Bronze with min, 50 micro-inch Tin plated
Wire size compatibility	23-26 AWG solid wire
Dimensions (WxHxD) mm	482 x 44 x 29
Performance	
IDC cap colour code supports both wiring schemes TIA 568A & 568B	
Insertion force	900 gm for 8 contacts
Retention strength	7.7kg between jack and plug
Operating temperature	-10°C to 60°C
Durability	Jack 750 cycles

UC^{CONNECT} 1U 24port Cat6 UTP 180° Punch Down Panel

Construction

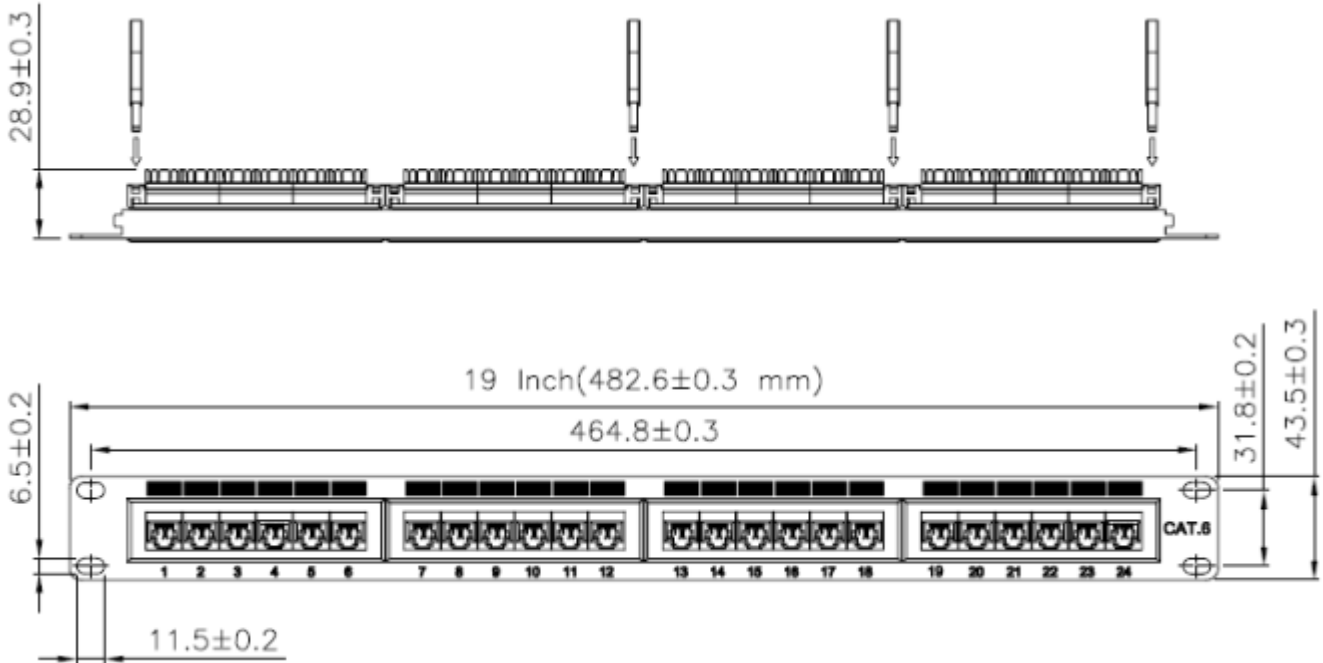

Technical data

Material Code	Material Description	Description Code	Weight	Items per Packaging Unit
1021290	YPWBP00110 1U 24port Cat6 UTP 180° Punchdown Panel in Black	UC C400 PW TR U BK 24 1U	545g	1 or 20
Related Products				
Material Code	Material Description	Description Code	Weight	Items per Packaging Unit
1021314	YSBPP00119 Support bar for 180° Patch Panel	UC CACC SB	267g	1 or 20

© PRYSMIAN GROUP 2013, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by Prysmian Group: any modification or alteration afterwards of product may give different result.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian Group. The information is believed to be correct at the time of issue. Prysmian Group reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorised by Prysmian Group.