


Draka UC^{Connect} Patch-Cords

Flexible cables with RJ45 connectors for specific channel performance

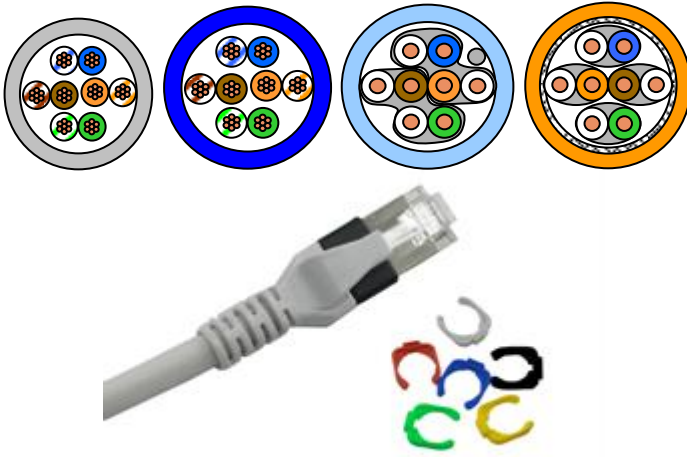

UC^{Connect} System Patch-Cords

- Flexible stranded bare copper conductor patch cable
- Flexible solid bar copper conductor CP-cable
- 2xRJ45 connector (TIA568-B coding)
- Proven performance
- Different jacketing options
- Different colour options (grey, blue, aqua, yellow, orange, red, green, black)
- DualBoot molded strain relief
- Latch protector

Specification



Product Family

UC^{Connect}300 Class D Channel, unshielded
 UC^{Connect}400 Class E Channel, unshielded
 UC^{Connect}500 Class Ea Channel, shielded
 UC^{Connect}500 Class Ea Channel, shielded

Related Cable Description

Cat.5e U/UTP 26/7 AWG 4P patch cable LSHF
 Cat.6 U/UTP 26/7 AWG 4P patch cable LSHF
 Cat.7 S/FTP 27/7 AWG 4P patch cable LSHF
 Cat.7 S/FTP 26/1 AWG 4P cable LSHF especially for CP application

Performance

Flame resistance - PVC
 Flame resistance - LSHF
 Standards
 Length

IEC 60332-1
 IEC 60332-1, IEC 60754-2, IEC 61034
 EN 50173, ISO/IEC 11801 Amendment 2, IEC 60603-7
 1m, 2m, 3m, & 5m other lengths upon request

Draka UC^{Connect} Patch-Cords

Flexible cables with RJ45 connectors for specific channel performance

Technical Data

Technical data

Material code	Material Description	Size	Weight	Items per packaging unit
YPCBP00134	UC C300 PC UU GY L 00100	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
YPCBP00135	UC C300 PC UU GY L 00200			
YPCBP00136	UC C300 PC UU GY L 00300			
YPCBP00137	UC C300 PC UU GY L 00500			
YPCBP00155	UC C400 PC UU GY L 00100	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
YPCBP00156	UC C400 PC UU GY L 00200			
YPCBP00157	UC C400 PC UU GY L 00300			
YPCBP00158	UC C400 PC UU GY L 00500			
YPCBP00170	UC C500 PC SF GY L 00100	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
YPCBP00171	UC C500 PC SF GY L 00200			
YPCBP00172	UC C500 PC SF GY L 00300			
YPCBP00173	UC C500 PC SF GY L 00500			

CM – length in centimeters

Standard colours acc. to table

Packaging option to be identified with order information

Related Products

Marking clips

YMCBP00183	UC CACC PC Marking Clip blue 50pc	50 pieces
YMCBP00184	UC CACC PC Marking Clip yellow 50pc	50 pieces
YMCBP00185	UC CACC PC Marking Clip green 50pc	50 pieces
YMCBP00186	UC CACC PC Marking Clip black 50pc	50 pieces
YMCBP00187	UC CACC PC Marking Clip red 50pc	50 pieces

© PRYSMIAN GROUP 2012, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by Prysmian Group: any modification or alteration afterwards of product may give different result.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian Group. The information is believed to be correct at the time of issue. Prysmian Group reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorised by Prysmian Group.