

Datacom Connectivity

Draka UC^{Connect} Patch-Cords

Flexible cables with RJ45 connectors for specific channel performance



Issue date: 08/10

Supersedes: 04/10

Page: 1/2



Value Innovation is a way of looking at the world. By combining market insight with technological know-how and building strong, long-lasting relationships, we add value to your business with advanced communication solutions and services that are designed to last. No matter how complex your challenge, we have a product or solution that will do more than meet your needs. New applications, breakthrough cables or complete network designs - it's all part of what we call Value Innovation, and it's what drives us.

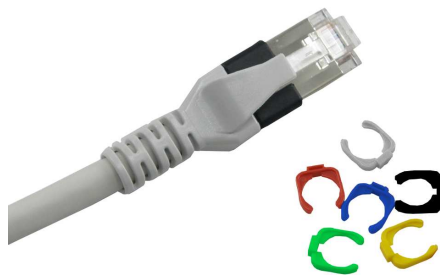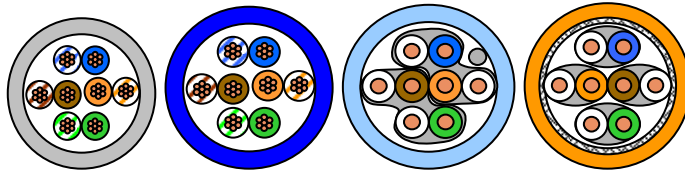

Patch-Cords compatible with UC^{Connect} system

- Flexible stranded bare copper conductor patch cable
- Flexible solid bar copper conductor CP-cable
- 2xRJ45 connector (TIA568-B coding)
- Proven performance
- Different jacketing options
- Different colour options (grey, blue, aqua, yellow, orange, red, green, black)
- DualBoot molded strain relief
- Latch protector

Specification

Product Family

UC ^{Connect} 300 Class D Channel, unscreened
UC ^{Connect} 400 Class E Channel, unscreened
UC ^{Connect} 500 Class Ea Channel, screened
UC ^{Connect} 500 Class Ea Channel, screened

Related Cable Description

Cat.5e U/UTP 26/7 AWG 4P patch cable LSHF
Cat.6 U/UTP 26/7 AWG 4P patch cable LSHF
Cat.6a F/UTP 27/7 AWG 4P patch cable LSHF
Cat.7 S/FTP 26/1 AWG 4P cable LSHF especially for CP application

Performance

Flame resistance - PVC	IEC 60332-1
Flame resistance - LSHF	IEC 60332-1, IEC 60754-2, IEC 61034
Standards	EN 50173, ISO/IEC 11801 Amendment 2, IEC 60603-7
Length	2m, 3m, other lengths upon request



Technical data				
Material code	Material Description	Size	Weight	Items per packaging unit
1021350-LLLLLCM 1021350-00250CM	UC C300 PC UU GY L XXXXX UC C300 PC UU GY L 00250	LLLLL: Length option; length in cm (example: 00250 → 2,5m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
1021360-LLLLLCM 1021360-00200CM	UC C400 PC UU BU L XXXXX UC C400 PC UU BU L 00200	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
1021370-LLLLLCM 1021370-00200CM	UC C500 PC FU AQ L XXXXX UC C500 PC FU AQ L 00200	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
1021380-LLLLLCM 1021380-01500CM	UC C500 CP SF OR L XXXXX UC C500 CP SF OR L 01500	LLLLL: Length option; length in cm (example: 01500 → 15,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
	CM – length in centimeters			
	Standard colours acc. to table			
	Packaging option to be identified with order information			
Related Products				
	Marking clips			
1021400	UC CACC PC Marking Clip grey 50pc			50 pieces
1021401	UC CACC PC Marking Clip blue 50pc			50 pieces
1021402	UC CACC PC Marking Clip yellow 50pc			50 pieces
1021403	UC CACC PC Marking Clip green 50pc			50 pieces
1021404	UC CACC PC Marking Clip black 50pc			50 pieces
1021405	UC CACC PC Marking Clip red 50pc			50 pieces