


# Draka UC<sup>Connect</sup> Patch-Cords

Flexible cables with RJ45 connectors for specific channel performance

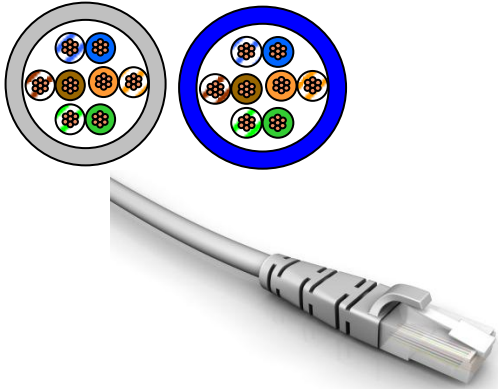

## UC<sup>Connect</sup> System Patch-Cords

- Flexible stranded bare copper conductor patch cable
- Flexible solid bar copper conductor CP-cable
- 2xRJ45 connector (TIA568-B coding)
- Proven performance
- Different colour options (grey, blue, aqua, yellow, orange, red, green, black)
- DualBoot moulded strain relief
- Latch protector

## Specification

<b>Product Family</b>	<b>Related Cable Description</b>
UC <sup>Connect</sup> 300 Class D Channel, unshielded	Cat.5e U/UTP 24 AWG 4P patch cable LSHF
UC <sup>Connect</sup> 400 Class E Channel, unshielded	Cat.6 U/UTP 24 AWG 4P patch cable LSHF
<b>Performance</b>	
Flame resistance - LSHF	IEC 60332-1, IEC 60754-2, IEC 61034
Standards	EN 50173, ISO/IEC 11801 Amendment 2, IEC 60603-7
Length	0.5m, 1m, 2m, 3m & 5m other lengths upon request

# Draka UC<sup>Connect</sup> Patch-Cords

Flexible cables with RJ45 connectors for specific channel performance

## Technical Data

### Technical data

Material code	Material Description	Size	Weight	Items per packaging unit
YPCBP00310	UC C300 PC UU GY L 00050 V1	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
YPCBP00311	UC C300 PC UU GY L 00100 V1			
YPCBP00312	UC C300 PC UU GY L 00200 V1			
YPCBP00313	UC C300 PC UU GY L 00300 V1			
YPCBP00314	UC C300 PC UU GY L 00500 V1			
YPCBP00316	UC C400 PC UU GY L 00050 V1	LLLLL: Length option; length in cm (example: 00200 → 2,0m)		Packaging option (1 = 1 per bag, 2 = 5 per bag, 3 = 10 per bag)
YPCBP00317	UC C400 PC UU GY L 00100 V1			
YPCBP00318	UC C400 PC UU GY L 00200 V1			
YPCBP00319	UC C400 PC UU GY L 00300 V1			
YPCBP00321	UC C400 PC UU GY L 00500 V1			
CM – length in centimeters				
Standard colours acc. to table				
Packaging option to be identified with order information				

© PRYSMIAN GROUP 2012, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by Prysmian Group: any modification or alteration afterwards of product may give different result.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian Group. The information is believed to be correct at the time of issue. Prysmian Group reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorised by Prysmian Group.